

## CONNECT AV EQUIPMENT IN ANY INSTALLATION

### Cables

**P568-xxx**  
HDMI, 4K 30 Hz (M/M)

**P568-xxx-8K6**  
HDMI, 8K 60 Hz, (M/M)

**P568F-xxx-8K6**  
HDMI, 8K 60 Hz, Plenum-Rated, (M/M)

**P568FM-xxx-8K6**  
HDMI, 8K 60 Hz AOC, (M/M)

**P569-xxx-CERT**  
HDMI + Ethernet, 4K 60 Hz, Gripping Connectors, (M/M)

**P580-xxx**  
DisplayPort, 4K 60 Hz, (M/M)

**P580-xxx-8K6**  
DisplayPort, 8K 60 Hz, (M/M)

**P580F3-xxx-8K6**  
DisplayPort Fiber, 8K 60 Hz, AOC, (M/M)

**P580F3-xxx-8K6**  
DisplayPort Fiber, 8K 60 Hz, AOC, (M/M)

**U420-C03-G2-5A**  
USB-C, 5A (100W) Charging, USB-IF Certified, (M/M)

**U444-xxx-DP8SE**  
USB-C to DP AOC, 8K @ 30 Hz, (M/M)

**U444-xxx-H4K6BE**  
USB-C to HDMI, (M/M)

**U520-31N**  
USB4 40 Gbps, (M/M)

**UVR-05M-CA-AOC**  
USB-A to C, VR Link AOC (Meta Quest 2), M/M

**MTB3-xxx**  
Thunderbolt 3, 20-40 Gbps (M/M)

### Adapters

**P130-06N-DP-8K**  
HDMI to DP with USB power, (M/F)

**P134-06N-VGA**  
DisplayPort to VGA, (M/F)

**P134-000**  
DisplayPort to DVI, (M/F)

**P136-000**  
DisplayPort to HDMI, (M/F)

**P131-06N**  
HDMI to VGA, (M/F)

**P132-08N**  
HDMI to DVI, (M/F)

**P139-06N-DP4K6B**  
Mini DP to DP, (M/F)

**P137-06N-HDMI**  
Mini DP to HDMI, (M/F)

**P130-000**  
HDMI to DVI-D, (F/M)

**P136-06N-HV-V2**  
DisplayPort to VGA/HDMI, (M/F/F)

**P136-06N-HDV-4K**  
DP to VGA/DVI/HDMI All-in-One Converter, (M/F/F/F)

### Extenders

**B127A-1A1-BDBDA**  
DisplayPort over Cat6 Kit

**B127A-111-BDTDA**  
DisplayPort 1.2a Kit

**B127A-1A1-BHBH**  
HDMI over Cat6 Kit, KVM Support

**B127A-111-BHTH**  
HDMI over Cat6 Kit

**B127A-1A1-FHFH**  
HDMI over Cat6 Wallplate Kit

**B127F-1A1-MMDDA**  
HDMI over Fiber Kit with USB

**B127F-1A1-MM-HH**  
HDMI over Fiber Kit

**B127U-002-PHPH2**  
2-Port HDMI over Cat6 Kit, 1x Pigtail Transmitter, 2x Pigtail Receivers

**B127-1A1-WHD3**  
HDMI Wireless Kit

**B127-1A1-WHD4CH**  
HDMI Wireless USB-C Mini Kit

**B127-1A1-WHD4HH**  
HDMI Wireless Mini Kit

### Splitters

**B118-002-8K**  
HDMI, 8K, 2-Port

**B118-004-8K**  
HDMI, 8K, 4-Port

**B118-008-4K**  
HDMI, 4K, 8-Port

**B118-002-HDR-V2**  
HDMI, 4K, 2-Port

**B140-002-DD**  
DVI over Cat5/6, 2-Port

**B127A-004-BHPH3**  
HDMI over Cat6, x3 Pigtail Receivers

**B156-003-8K**  
DisplayPort, 8K, 3-Port MST Hub

**B156-003-H8K**  
DP to HDMI, 8K, 3-Port MST Hub 1x Pigtail Transmitter, 2x Pigtail Receivers

**B156E-003-8K-K**  
DP to DP, 8K, 3-Port MST Hub

**B156E-003-H8K-K**  
DP to HDMI, 8K, 3-Port MST Hub Kit

### KVM Switches

**B005-DPUA4**  
DisplayPort/USB, 4-Port

**B005-HUA4**  
HDMI/USB, 4-Port

### Switches

**B127A-4X4-BH4PH**  
HDMI over Cat6 4x4 Matrix Kit

**B119-005-UHD**  
HDMI, 5-Port

**B119-4X2-4K**  
HDMI 4x2 Matrix

**B119-4X4-4K**  
HDMI 4x4 Matrix

### USB-C Docks

**U442-DOCK2-S**  
USB-C, Dual Display, HDMI/mDP, VGA, USB-A/C, GbE, 60W PD Charging

**U442-DOCK1**  
USB-C, Dual Display, HDMI/mDP, VGA, USB-A/C, GbE, 100W PD Charging

**MTB3-002-HD**  
Thunderbolt 3 to HDMI Adapter, Dual Monitor

**U444-06N-H4GUC2**  
USB-C Multiport Adapter, HDMI, USB 3.x, GbE, 100W PD Charging

### HDBaseT

**BHDBT3-TR**  
HDMI, 4K, Transmitter/Receiver

### In Line Surge

**B110-SP-HDMI-1**  
HDMI, 4K

**B110-SP-10G**  
Cat6A, 10 Gbps

## MOUNT AV EQUIPMENT IN ANY INSTALLATION

### Monitor risers



**MR1411M**  
14 x 9"



**MR1612D1**  
15.5 x 11.25", Storage Drawer



**MR2208G**  
8 x 22", Glass Top



**MR159D**  
14.6 x 9.25", Storage Drawer



**MR4010**  
39.4 x 10.2", Wood



**MR229USB**  
21.8 x 8.5", x3 USB



**MR248USBG**  
24.1 x 8.3", Glass Top, x5 USB



**DDR811TRAYTAA**  
10 x 12", Tray



**WWSSC2414TAA**  
24 x 14", Clamp

### Tablet mounts



**DMTB413**  
Fits 4.7-12.9" Tablets



**DMTBD413**  
Fits 4.7-12.9" Tablets, Flex Arm



**DMTBS911**  
Fits 9.7-10.5" Tablets, Floor Stand



**DMTB11**  
Fits 9.7-11" Tablets, Wall Mount



**DMTB911**  
Fits 9.7-11" Tablets, Wall or Desk Mount



**DMTBS13**  
Fits 13" Tablets, Floor Stand

### Carts and Stands



**WWSS1DWSTAA**  
Mobile Workstation



**DMCS3255SG62W**  
Fits 32-55" Screens  
Frosted Glass Base/  
Shelves



**DMCS3270XP**  
Fits 32-70" Screens



**DMCS3770L**  
Fits 37-70" Screens



**DMPDS3770TRIC**  
Fits 37-70" Screens,  
Portable Stand



**DMCS60100XX**  
Fits 60-100" Screens



**WWSSRC**  
Rolling Desk/TV  
Cart



**WWSSRDSTC**  
Rolling Desk,  
CPU Shelf

### Fixed wall mounts



**DWF1327M**  
Fits 13-27" Screens



**DWF3780X**  
Fits 37-80" Screens



**DWFSC3780MUL**  
Fits 37-80" Screens  
UL Certified



**DWFPC4570M**  
Fits 45-70" Screens



**DWF60100XX**  
Fits 60-100" Screens

### Tilt wall mounts



**DWT1327S**  
Fits 13-27" Screens




**DWT2655XP**  
Fits 26-55" Screens



**DWT3770X**  
Fits 37-70" Screens



**DWTSC3780MUL**  
Fits 37-80" Screens

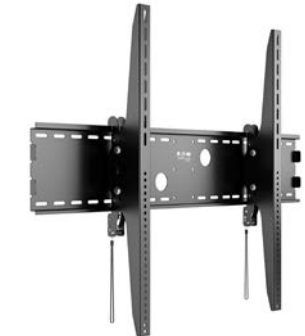

**DWT60100XX**  
Fits 60-100" Screens

### Swivel/tilt wall mounts



**DWM1327SE**  
Fits 13-27" Screens



**DWM1327SP**  
Fits 13-27" screens,  
Screen Adjustment



**DWM1742MA**  
Fits 17-42" Screens,  
UL Certified



**DWM1742MN**  
Fits 17-42" Screens



**DWM2655M**  
Fits 26-55" Screens



**DWM3780ROT**  
Fits 37-80" Screens



**DWM5070HD**  
Fits 50-70" Screens



**DWM60100XX**  
Fits 60-100" Screens



**DWMLARM1732AM**  
Fits 17-32" Screens

### Desktop mounts



**DDR1327SE**  
Fits 13-27" Screens



**DDR1327SDD**  
Fits (x2) 13-27" Screens



**DDR1730TAL**  
Fits (x3) 17-30" Screens



**DMPDT1732AM**  
Fits (x3) 17-32" Screens