

Eaton's Wiring Devices  
Smart home devices

# Smart home devices

Simple, intuitive solutions for  
home automation, connectivity  
and energy management

**EATON**

*Powering Business Worldwide*



# Smart home

Eaton's smart home is designed for reliability, easy installation, and added convenience. Select the best option for your smart home with the broad selection of Wi-Fi and Z-Wave Plus devices. The features built in to the products are designed to create a seamless installation and peak device performance. Control the devices from anywhere and transform your home to make every room more livable.


## Smart home families

<b>Smart home family intro</b>	3
<b>Wi-Fi smart devices</b>	4-5
Wi-Fi smart voice dimmer	6
Wi-Fi smart universal dimmer	7
Accessory dimmer	7
Wi-Fi smart switch	8
Wi-Fi smart duplex receptacle	9
<b>Z-Wave Plus wireless collection</b>	11
Z-Wave Plus wireless universal dimmer	12
Z-Wave Plus wireless accessory dimmer	12
Z-Wave Plus wireless switch	13
Z-Wave Plus wireless accessory switch	13
Z-Wave Plus wireless duplex receptacle	14
Z-Wave Plus wireless motion sensor	15
Z-Wave Plus wireless ON/OFF plug-in module	15




### Wi-Fi smart

Set up quickly and easily with Amazon's Alexa App – no hubs or controllers are necessary.

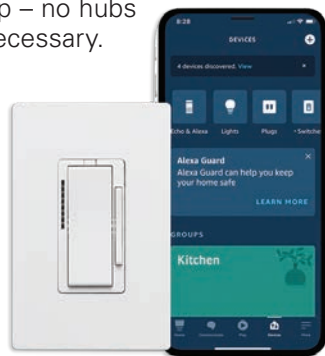


### Z-Wave Plus™

Wireless mesh network provides faster and more secure performance and interoperability, with all products communicating with each other through a hub.

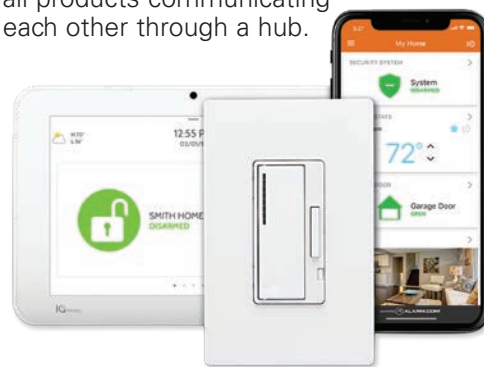


#### Wi-Fi smart devices

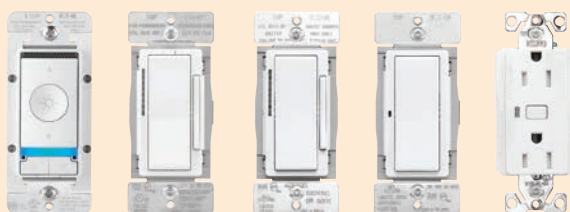

Page 4

#### Z-Wave Plus devices

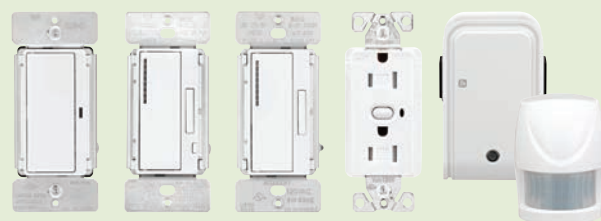

Page 11

See how much smarter a smart home can be with Eaton



# Eaton's Wi-Fi smart devices

Eaton's broad selection of Wi-Fi smart devices offer reliability with unbeatable ease of setup. Every device sets up quickly and easily with the free Amazon Alexa App—no hubs or controllers are necessary. You can even add voice-control using any Alexa built-in device.







For more information on the complete Wi-Fi smart product portfolio please visit [www.eaton.com/smarthome](http://www.eaton.com/smarthome)



Amazon, Alexa and all related logos are trademarks of Amazon.com, Inc. or its affiliates.

## Wi-Fi smart devices

<p>Wi-Fi smart voice dimmer</p>  <p><b>Page 6</b></p>	<p>Wi-Fi smart universal dimmer and accessory dimmer</p>  <p><b>Page 7-8</b></p>	<p>Wi-Fi smart switch</p>  <p><b>Page 9</b></p>	<p>Wi-Fi smart duplex receptacle</p>  <p><b>Page 10</b></p>
--	---	---	--



**Frustration-Free Setup**  
Just turn on your device and set up is simple using the Amazon Alexa App.



**Voice control**  
Just ask Alexa to turn your lights ON/OFF or brighten/dim lights when used with any Alexa built-in device.



**Personalization**  
Schedule lights to go on and off—and even dim—to fit a daily routine.



**No hub required**  
Quickly and easily set up a wide variety of smart-home lighting-control devices without hubs or controllers.



**Easy installation**  
LED indicators confirm proper installation and eliminate callbacks.



**Up-to-date**  
Ensure you have the latest features and peak device performance through over the air updates.






## Enjoy Frustration-Free Setup with the Amazon Alexa App

Every device sets up quickly and easily with the free Amazon Alexa App-no hubs or controllers are necessary.



### 3 Easy steps to set up your Wi-Fi smart device

- 1 Install your Wi-Fi smart device
- 2 Download the Amazon Alexa App via the App store
- 3 Add your device to Amazon Alexa App

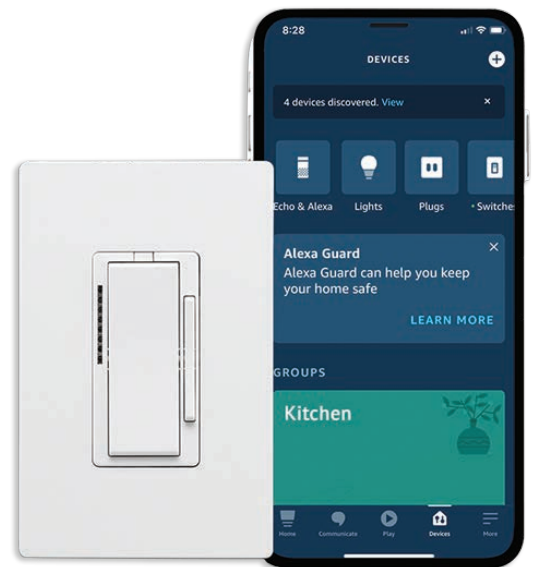

Set up your Wi-Fi smart device in  
the Amazon Alexa App

# Wi-Fi smart devices

## Wi-Fi smart voice dimmer

### Product description

Single pole, 3-way, multi-location

120V/AC, 60Hz

Rated for all common lighting loads—dimmable LED, dimmable CFL, INC/HAL, ELV, MLV, FLR

### Design features

- Set up and control dimmer using the Amazon Alexa App or by voice commands with Alexa built-in
- No hub required
- Neutral wire required for installation
- Compatible with regular 3-way switch for 3-way control
- Air-gap switch disconnects power to dimmer and load
- Adjustable high-level trim setting for additional energy savings
- Adjustable low-level trim setting helps prevent flickering
- LED indicator bar indicates selected light level
- When the lights are OFF, press and hold the ON/OFF button for 2 seconds. The device will then instantly turn ON at its maximum brightness level
- When the lights are ON, press and hold ON/OFF button for 2 seconds and the device will delay 10 seconds before turning OFF lights
- LED indicator system alerts if the device is not set up in the network
- Preset whether the devices comes on or stays off following a power outage
- Supports multiple languages - English, French, Spanish

*“Alexa, announce ‘dinner is ready’.”*



WFAVD30  
(PJS26W wallplate  
sold separately)



### Wi-Fi smart voice dimmer

W	Rating		Compatible lamp types	Description	Color suffix	Catalog no.
	V/AC	Hz				
300	120	60	Dimmable LED/CFL, INC, HAL, FLR, MLV, ELV	Wi-Fi smart voice dimmer	W	<input type="checkbox"/> WFAVD30-__

### Color ordering information:

For ordering devices, include Catalog No. followed by the Color Suffix: W (White)



(White)

Amazon, Alexa and all related logos are trademarks of Amazon.com, Inc. or its affiliates.

**Compliances, specifications and availability are subject to change without notice.**

 Indicates CA Title 24 compliant



# Wi-Fi smart devices

## Wi-Fi smart universal dimmer

### Product description

Single pole, 3-way, multi-location

120V/AC, 60Hz

Rated for all common lighting loads—dimmable LED, dimmable CFL, INC/HAL, ELV, MLV, FLR

### Design features

- Set up and control dimmer using the Amazon Alexa App or by voice commands
- No hub required
- LED indicator system alerts if the device is not set up in the network
- Pressing and holding ON button for 2 seconds brings light to full brightness without affecting preset levels
- When the lights are ON, press and hold OFF button for 2 seconds and the device will delay 10 seconds before turning OFF lights
- Preset whether your device comes on or stays off following a power outage
- Adjust how long lights stay on to allow for a safe, convenient exit
- Neutral required for installation
- Dimmable seven step white LED indicators alongside push pad indicates selected light level
- Adjustable high-end trim level setting for additional energy savings and low-end trim level setting helps prevent flickering
- Programmable rapid start feature ensures lamp start-up even at low dim levels
- Air gap switch disconnects power to dimmer and load
- Compatible with accessory dimmer (WACD) or standard 3-way switch for multi-location control



WFD30  
(PJS26W wallplate  
sold separately)



### Wi-Fi smart universal dimmer



W	Rating		Compatible lamp types	Description	Color suffix	Catalog no.
	V/AC	Hz				
450	120	60	Dimmable LED/CFL	Wi-Fi smart universal dimmer	LA, W, C2, C6, C7	<input type="checkbox"/> WFD30__
600	120	60	INC, HAL, FLR, MLV, ELV			

### Color ordering information

For ordering devices, include Catalog no. followed by the Color suffix: LA (Light Almond), W (White), C2 (Color Change Kit: LA, W, V), C6 (Color Change Kit: W, RB, SG), C7 (Color Change Kit: BK, B, GY)

LA	W		W	RB	SG	BK	B	GY
(Light Almond)	(White)							
C2 Color Change Kit			C6 Color Change Kit			C7 Color Change Kit		
LA (Light Almond), W (White), V (Ivory)			W (White), RB (Oil Rubbed Bronze), SG (Silver Granite)			BK (Black), B (Brown), GY (Gray)		

Amazon, Alexa and all related logos are trademarks of Amazon.com, Inc. or its affiliates.

**Compliances, specifications and availability are subject to change without notice.**

**TITLE 24** Indicates CA Title 24 compliant

# Wi-Fi smart devices

## Accessory dimmer

### Product description

3-way  
120V/AC, 60Hz,

### Design features

- Does not control a load
- Compatible only with Wi-Fi smart universal dimmer (WFD30) for multi-location control
- LED indicator system alerts if the device is not connected to the Wi-Fi smart universal dimmer
- Neutral wire required for installation
- Dimmable seven step white LED display alongside push pad indicates selected light level – even in full daylight (coordinates light level status with connected Wi-Fi smart universal dimmer)
- When the lights are ON, press and hold OFF button for 2 seconds and the device will delay 10 seconds before turning OFF lights



WACD  
(PJS26W wallplate  
sold separately)

### Accessory dimmer

A	Rating		Description	Color suffix	Catalog no.
	V/AC	Hz			
-	120	60	Accessory dimmer compatible with Wi-Fi smart universal dimmer (WFD30)	LA, W, C2, C6, C7	□ WACD__

### Color ordering information

For ordering devices, include Catalog no. followed by the Color suffix: LA (Light Almond), W (White), C2 (Color Change Kit: LA, W, V), C6 (Color Change Kit: W, RB, SG), C7 (Color Change Kit: BK, B, GY)

LA	W							
(Light Almond)	(White)							
LA	W	V	W	RB	SG	BK	B	GY
C2 Color Change Kit			C6 Color Change Kit			C7 Color Change Kit		
LA (Light Almond), W (White), V (Ivory)			W (White), RB (Oil Rubbed Bronze), SG (Silver Granite)			BK (Black), B (Brown), GY (Gray)		

Amazon, Alexa and all related logos are trademarks of Amazon.com, Inc. or its affiliates.

**Compliances, specifications and availability are subject to change without notice.**

**TITLE 24** Indicates CA Title 24 compliant



# Wi-Fi smart devices

## Wifi smart switch

### Product description

Single pole, 3-way  
15A, 120V/AC, 60Hz, 1/2 HP

### Design features

- Set up and control switch using the Amazon Alexa App or by voice commands
- No hub required
- LED indicator system alerts if the device is not set up in the network
- Preset whether your device comes on or stays off following a power outage
- When the lights are ON, press and hold OFF button for 2 seconds and the device will delay 10 seconds before turning OFF lights
- Neutral required for installation
- Dimmable white LED indicator illuminates to indicate ON/OFF status
- Can be wired with standard 3-way switch where traveler wire exists for 3-way
- Rated for 1/2 HP motor loads



WFSW15  
(PJS26W wallplate  
sold separately)



Wi-Fi smart switch   

A	Rating		Description	Color suffix	Catalog no.
	V/AC	Hz			
15	120	60	Wi-Fi smart switch	W, LA, C2, C6, C7	<input type="checkbox"/> WFSW15__

### Color ordering information

For ordering devices, include Catalog no. followed by the Color suffix: LA (Light Almond), W (White), C2 (Color Change Kit: LA, W, V), C6 (Color Change Kit: W, RB, SG), C7 (Color Change Kit: BK, B, GY)

LA	W							
(Light Almond)	(White)							
LA	W	V	W	RB	SG	BK	B	GY
C2 Color Change Kit			C6 Color Change Kit			C7 Color Change Kit		
LA (Light Almond), W (White), V (Ivory)			W (White), RB (Oil Rubbed Bronze), SG (Silver Granite)			BK (Black), B (Brown), GY (Gray)		

Amazon, Alexa and all related logos are trademarks of Amazon.com, Inc. or its affiliates.

**Compliances, specifications and availability are subject to change without notice.**

# Wi-Fi smart devices

## Wi-Fi smart duplex receptacle

### Product description

2-pole, 3-wire grounding  
15A, 125V/AC, 60Hz, 1/2 HP

### Design features

- Set up and control receptacle using the Amazon Alexa App or by voice commands
- No hub required
- LED indicator system alerts if the device is not set up in the network
- Preset whether your device comes on or stays off following a power outage
- When the lights are ON, press and hold ON/OFF button for 2 seconds and the device will delay 10 seconds before turning OFF lights
- Neutral required for installation
- Dimmable white LED indicator illuminate to indicate ON/OFF status
- Provides control of one outlet leaving the other one for normal use
- One outlet can be controlled with a single pole switch
- Rated for 1/2 HP motor loads
- For added safety, complies with NEC specification that states all receptacles installed in dwelling units must be tamper resistant



WFTRCR15  
(PJS26W wallplate  
sold separately)



### Wi-Fi smart duplex receptacle



A	Rating		Description	Color suffix	Catalog no.
	V/AC	Hz			
15	125	60	Wi-Fi smart duplex receptacle	B, BK, GY, LA, RB, SG, V, W	□ WFTRCR15__

### Color ordering information:

For ordering devices, include Catalog No. followed by the Color Suffix: B (Brown), BK (Black), GY (Gray), LA (Light Almond), RB (Oil Rubbed Bronze), SG (Silver Granite), V (Ivory), W (White)



Amazon, Alexa and all related logos are trademarks of Amazon.com, Inc. or its affiliates.

**Compliances, specifications and availability are subject to change without notice.**

Tamper resistant

# Eaton's Z-Wave Plus Wireless Collection





Includes a broad lineup of lighting controls including wireless universal dimmer, wireless accessory dimmer, wireless switch, wireless accessory switch & wireless duplex receptacle. All these devices feature Z-Wave Plus Technology, improved communication range, S2 security, lower power consumption & over the air updates. Available in 2 unique physical styles and 10 different colors, this allows the users to match the devices to their home décor and designs.



For more information on the complete Z-Wave Plus wireless collection product portfolio please visit [www.eaton.com/smarthome](http://www.eaton.com/smarthome)



## Z-Wave Plus wireless collection

<p>Z-Wave Plus wireless universal dimmers &amp; accessory dimmer</p>  <p><b>Page 12</b></p>	<p>Z-Wave Plus wireless switches &amp; accessory switches</p>  <p><b>Page 13</b></p>	<p>Z-Wave Plus wireless duplex receptacle</p>  <p><b>Page 14</b></p>	<p>Z-Wave Plus wireless motion sensor &amp; plug-in module</p>  <p><b>Page 15</b></p>
--	---	---	--



### Hub required

In order for the devices to be controlled remotely, a compatible Z-Wave hub/controller is required



### App based control

Control your devices remotely



### Voice control when used with a compatible hub

Just ask Alexa or say Hey Google to turn your lights ON/OFF or brighter/dim lights when used with a compatible controller



### Secure network

All devices support S2 security and can be installed securely in the network for additional peace of mind



### Works with leading smart home systems

Interoperability powered by Z-Wave Plus technology enables compatibility with popular smart home and security systems



### Personalization

Set scenes, events, and groups to fit your daily routine. Z-Wave Plus devices also come in multiple styles and colors to match any decor





# Z-Wave Plus wireless collection

## Z-Wave Plus wireless universal dimmer and accessory dimmer

### Product description

Single pole, 3-way, and multi- location  
120V/AC, 60Hz

Rated for all common lighting loads—dimnable LED, dimmable CFL, INC/HAL, ELV, MLV, FLR

### Design features

- Adjustable low-end and high-end dimming range to prevent lamp flickering and for additional energy savings
- No de-rating required in multi-gang installations
- Compatible with Z-Wave Plus accessory dimmer (RF9642-Z) for wireless 3-way control, eliminating the need for traditional 3-way wiring or dedicated traveler wire
- Can be associated with up to 5 other Z-Wave Plus devices
- Programmable rapid start and delayed off fading up to 2 minutes (default is 10 seconds)
- Dimmable seven step blue dimmable LED display alongside push pad indicates selected light level and reduces brightness when OFF (nightlight feature)
- Air-gap switch disconnects power from load forcing an OFF condition
- Pressing and holding push pad for 2 seconds brings light to full brightness without affecting preset levels
- Neutral wire required for installation
- Child lockout feature disables local control at dimmer
- Supports Z-Wave Plus functionality with S2 security certification
- Preset whether your device comes on or stays off following a power outage



RF9643-NAW



RF9643-NDW



RF9642-ZDW

### Z-Wave Plus wireless universal dimmer and accessory



Rating		Hz	Compatible lamp types	Description	Designer color suffix	Decorator color suffix	Catalog no.
W/AC	V/AC						
300	120	60	Dimmable LED/CFL	Z-Wave Plus wireless universal dimmer, single pole/multi-location with presets and LEDs, neutral required	AW, DS, WS	DB, DBK, DGY, DLA, DRB, DSG, DW	<input type="checkbox"/> RF9643-N__
600	120	60	INC, ELV, MLV, FLR	Z-Wave Plus wireless accessory dimmer compatible only w/Z-Wave Plus wireless dimmers (RF9643-N)	AW, DS, WS	DB, DBK, DGY, DLA, DRB, DSG, DW	<input type="checkbox"/> RF9642-Z__

Complies with Z-Wave Plus, FCC, cULus, NOM certified

### Rated for all common lighting loads



### Color ordering information:

For ordering devices, include Catalog No. followed by the Color Suffix: AW (Alpine White), DS (Desert Sand), WS (White Satin), DB (Decorator Brown), DBK (Decorator Black), DGY (Decorator Gray), DLA (Decorator Light Almond), DRB (Decorator Oil Rubbed Bronze), DSG (Decorator Silver Granite), DW (Decorator White).

### Designer series color options:



### Decorator series color options:



Compliances, specifications and availability are subject to change without notice.

**TITLE 24** Indicates CA Title 24 compliant

# Z-Wave Plus wireless collection

## Z-Wave Plus wireless switch and accessory switch

### Product description

Single pole, 3-way, multi-location  
1/2 HP, 15A, 120V/AC, 60 Hz  
LED, CFL, INC/HAL, MLV, ELV, FLR



RF9601AW



RF9601DW



RF9617DW

### Design features

- Compatible with Z-Wave Plus accessory switch (RF9617) for wireless 3-way control eliminating the need for traditional 3-way wiring
- Can be wired with standard 3-way switch (7501)
- Can be associated with up to 5 other Z-Wave Plus devices
- Dimmable blue LED at center right of paddle illuminates to indicate ON/OFF status
- Patented indicator system alerts if the device is not set up in the network
- Programmable delayed OFF mode up to 2 minutes (default is 10 seconds)
- Preset whether your devices comes on or stays off following a power outage
- Neutral wire required for installation
- Supports panic mode with compatible hubs
- Child lockout feature disables local control at switch
- Supports Z-Wave Plus functionality with S2 security certification

### Z-Wave Plus wireless switch and accessory



A	Rating		Description	Designer color suffix	Decorator color suffix	Catalog no.
	V/AC	Hz				
15	120	60	Z-Wave Plus wireless switch, single pole, 3-way	AW, DS, WS	DB, DBK, DGY, DLA, DRB, DSG, DW	<input type="checkbox"/> RF9601__
	120	60	Z-Wave Plus accessory switch, compatible with RF9601	AW, DS, WS	DB, DBK, DGY, DLA, DRB, DSG, DW	<input type="checkbox"/> RF9617__

Complies with Z-Wave Plus, FCC Part 15, Class B; cULus Listed to UL1472, file no. E47967, certified to CSA C22.2 no. 187.1; NOM certified

### Color ordering information:

For ordering devices, include Catalog No. followed by the Color Suffix: AW (Alpine White), DS (Desert Sand), WS (White Satin), DB (Decorator Brown), DBK (Decorator Black), DGY (Decorator Gray), DLA (Decorator Light Almond), DRB (Decorator Oil Rubbed Bronze), DSG (Decorator Silver Granite), DW (Decorator White).

#### Designer series color options:

AW	AW	DS	DS	WS	WS
(Alpine White)		(Desert Sand)		(White Satin)	

#### Decorator series color options:

DB	DBK	DGY	DLA	DRB	DSG	DW
(Decorator Brown)	(Decorator Black)	(Decorator Gray)	(Decorator Light Almond)	(Decorator Oil Rubbed Bronze)	(Decorator Silver Granite)	(Decorator White)



Compliances, specifications and availability are subject to change without notice.

# Z-Wave Plus wireless collection

## Z-Wave Plus wireless duplex receptacle

### Product description

2-pole, 3-wire grounding  
15A, 125V/AC, 60Hz, 1/2 HP



5-15R



RFTR9605-TWS



### Design features

- For added safety, complies with NEC® specification that states all receptacles installed in dwelling units must be tamper resistant
- Offers UL Listed safety shutter system that prevents insertion of foreign objects into receptacle
- Provides Z-Wave control of one outlet leaving the other one for normal use
- Ability to be controlled remotely by other Z-wave devices through association (Z-Wave Plus devices only)
- Can be wired with standard 3-way switch where traveler wire exists for 3-way
- Dimmable blue LED at center right of paddle illuminates to indicate ON/OFF status



- Patented built-in wire stripper for #14 and #12 wire to speed installation
- Patented indicator system alerts if the device is not set up in the network
- Rated for 1/2 HP motor loads
- Preset whether your devices comes on or stays off following a power outage
- Supports panic mode with compatible hubs
- Child lockout feature disables local control at receptacle
- Supports Z-Wave Plus functionality with S2 security certification

### Z-Wave Plus wireless duplex receptacle



Rating		NEMA	Description	Color suffix	Catalog no.
A	V/AC				
15	125	5-15R	Tamper resistant split control duplex receptacle	AW, DS, WS, B, BK, LA, GY, RB, SG	□ RFTR9605-T__

Complies with Z-Wave Plus, FCC Part 15, Class B; cULus Listed to UL38DS, file no. E325082; NOM certified

### Color ordering information:

For ordering devices, include Catalog No. followed by the Color Suffix: AW (Alpine White), DS (Desert Sand), WS (White Satin), B (Brown), BK (Black), GY (Gray), LA (Light Almond), RB (Oil Rubbed Bronze), SG (Silver Granite).

AW	AW	DS	DS	WS	WS
(Alpine White)		(Desert Sand)		(White Satin)	
B	BK	GY	LA	RB	SG
(Brown)	(Black)	(Gray)	(Light Almond)	(Oil Rubbed Bronze)	(Silver Granite)



Compliances, specifications and availability are subject to change without notice.

Tamper resistant



# Z-Wave Plus wireless collection

## Z-Wave Plus wireless motion sensor

### Product description

120 degree wide detection zone  
1000 sq. ft.



RF96PIRBMS

### Design features

- Detects motion in a space with in-built Passive Infra-red and light sensor
- When used with a compatible smart hub, get alerted on your smart phone or tablet, trigger scenes or have lights come ON automatically
- CR123A Lithium battery included with the product provides expected battery life of 2 years
- Can be mounted using included screws or double sided tape
- 120° field of view with 1000 sq. ft coverage for major motion
- Supports Z-Wave Plus functionality with S2 security certification

### Z-Wave Plus wireless motion sensor

Coverage Area	Description	Color	Catalog no.
1000 sq. ft. 120° wide detection zone	Z-Wave Plus wireless motion sensor	W	□ RF96PIRBMS

## Z-Wave Plus wireless ON/OFF plug-in module

### Product description

12A - 120V/AC/c.a./CA; 60Hz  
1400W resistive load, 600W incandescent load,  
320W LED load



RF96APM

### Design features

- Provides wireless control of one outlet leaving the other outlet always ON
- Can be associated with up to 4 other devices
- Voice and app based control when used with compatible Z-Wave controller
- Supports Z-Wave Plus functionality with S2 security certification

### Z-Wave Plus wireless ON/OFF plug-in module

A	Rating V/AC Hz	Description	Color	Catalog no.
12	120 60	Z-Wave Plus wireless ON/OFF plug-in module	W	□ RF96APM

### Color ordering information

For ordering devices, include Catalog no. followed by the Color suffix: W (White)



(White)



Compliances, specifications and availability are subject to change without notice.

# We make what matters work.\*

\* At Eaton, we believe that power is a fundamental part of just about everything people do. Technology, transportation, energy and infrastructure—these are things the world relies on every day. That's why Eaton is dedicated to helping our customers find new ways to manage electrical, hydraulic and mechanical power more efficiently, safely and sustainably. To improve people's lives, the communities where we live and work, and the planet our future generations depend upon. Because that's what really matters. And we're here to make sure it works.

See more at [Eaton.com/whatmatters](http://Eaton.com/whatmatters)

Visit our website:  
[www.eaton.com/smarthome](http://www.eaton.com/smarthome)

Electrical Sector  
203 Cooper Circle  
Peachtree City, GA 30269  
United States  
Eaton.com  
Eaton.com/smarthome

**Eaton**  
1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
Eaton.com

© 2021 Eaton  
All Rights Reserved  
Printed in USA  
Publication No. BR610072EN  
December 2021

Electrical Sector  
Canada Operations  
5925 McLaughlin Road  
Mississauga, Ontario, L5R 1B8  
Canada  
EatonCanada.ca  
Eaton.com/smarthome

Eaton is a registered trademark.  
All other trademarks are property  
of their respective owners.

Electrical Sector  
Mexico Operations  
Carr. Tlalnepantla -  
Cuautitlan Km 17.8 s/n  
Col. Villa Jardin esq.  
Cerrada 8 de Mayo  
Cuautitlan, Mexico CP 54800  
Mexico  
Eaton.mx  
Eaton.com/smarthome

Follow us on social media to get the  
latest product and support information.

